
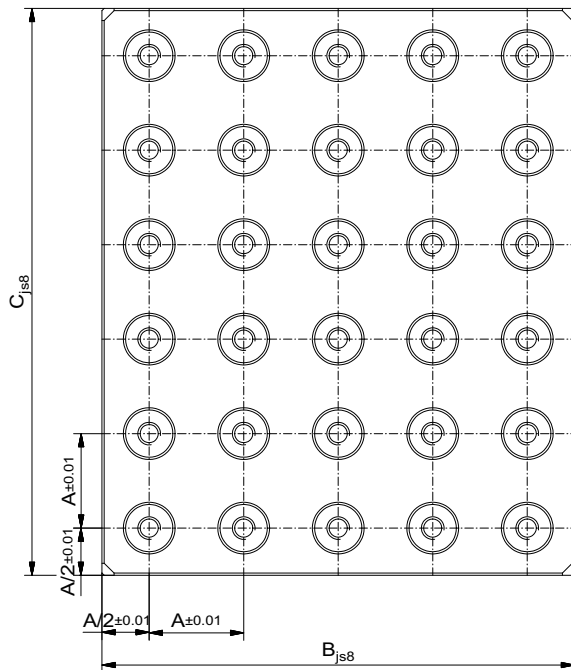


ALUFIX Grid Base Plates

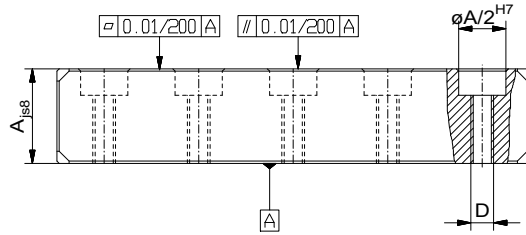


ALUFIX 16, Grid (A) 16, hole diameter 8mm

Nr.	A	B	C	D	g
20640	16	128	256	M4	1.416
20641	16	160	320	M4	2.221
20642	16	192	256	M4	2.123
20643	16	192	384	M4	3.185
20644	16	256	320	M4	3.539
20645	16	256	384	M4	4.247
20646	16	320	320	M4	4.424
20647	16	320	640	M4	8.847
20648	16	384	384	M4	6.370
20649	16	384	512	M4	8.493

ALUFIX 25, Grid (A) 25, hole diameter 12,5mm

Nr.	A	B	C	D	g
20387	25	200	400	M6	5.400
20388	25	250	500	M6	8.438
20403	25	300	400	M6	8.100
20386	25	300	600	M6	11.250
22923	25	400	500	M6	13.500
22925	25	400	600	M6	16.200
20439	25	500	500	M6	16.875
20381	25	500	1000	M6	33.750
20382	25	600	600	M6	24.300
20384	25	600	800	M6	32.400

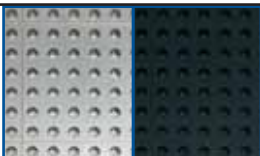

ALUFIX CLASSIC base plates can be anodized in different colours. The colour natural is standard, black (-1) is available as an alternative. Other colours on request

Other dimensions on request