



Meisterbock screw

with fixation pin to zero, lift +/- 3mm

without cap

Nr.	A	g
91777	84	98
282330	65	89

convex R18 with magnet

Nr.	A	g
90694	84	110
98031	65	100

convex R8

Nr.	A	g
91604	84	100
98033	65	90

convex R18

Nr.	A	g
90693	84	96
98034	65	86

flat with magnet








Nr.	A	g
93318	84	105
98032	65	95

flat

Nr.	A	g
93319	84	98
98035	65	90

with thread

Nr.	A	g
91912	84	90
98036	65	82

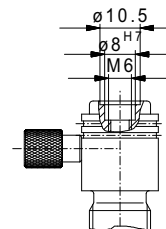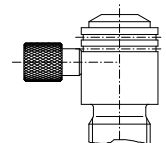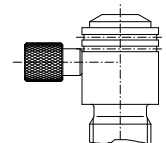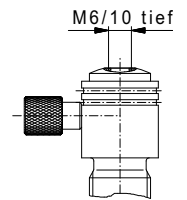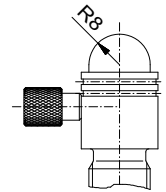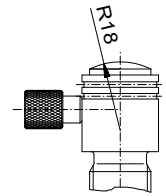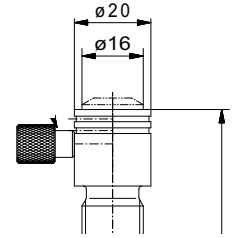


Special meisterbock screws i.e. with micrometer fine adjustment available on request.

Shim

0,5/0,05, for meisterbock screw

Nr.	A	B
13374	16	22

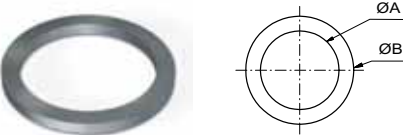

Spacer

for meisterbock screw

Nr.	A	B	C	D
53978	16	5	26	2,8

