


## Autocenter

spring loaded


Nr.	A	B	C	D	E	F	G	min.ø	max.ø	
81212	24x1	32	50	18	60	61	12,5	1	10	40

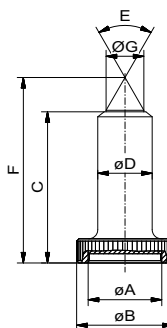

## Autocenter


spring loaded, with check pin

Nr.	A	B	C	D	E	F	G	min.ø	max.ø	
82252	24x1	32	50	18	15,5	71,5	6	7	19	60

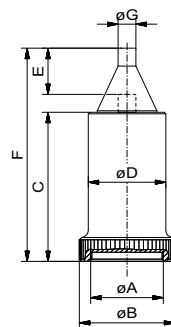

## True line stud

Nr.	A	B	C	D	E	F	
80590	M24x1	32	32,6	15	65	10	30
80661	M24x1	32	77,6	15	65	10	45
80591	M32x1	42	37,6	20	65	10	36
80666	M32x1	42	122,6	20	65	10	83

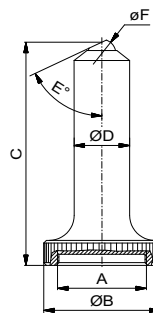


True line studs are also available in polymer (POM, black) on request

## Center

with ball

Nr.	A	B	C	D	E	F	
90545	M24x1	32	34	15	60	10	27
80584	M24x1	32	52	12,5	60	6	21
80585	M24x1	32	53	12,5	60	8	22
80586	M32x1	42	72	20	60	6	60
80587	M32x1	42	73	20	60	8	57
80588	M32x1	42	74	20	60	10	63
80589	M32x1	42	75	20	60	12	60

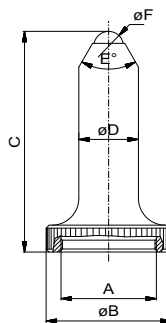

Centers with ball are also available in polymer (POM, black) on request



**ALUFIX CLASSIC** elements can be anodized in different colours. The colour natural is standard, black (-1) is available as an alternative. Other colours on request.

Other dimensions on request